


Training Large AI Models Consumes Massive Power - Who Will Be the Next-Gen AI “Power Manager”?

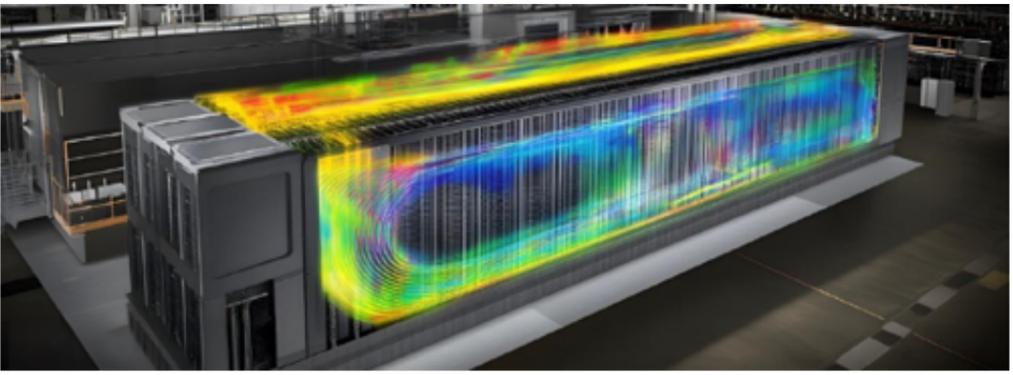

Gartner’s analysis of the top 10 strategic technology trends for 2026 reveals a fundamental shift in the arena of technology, signaling a clear message to all technology decision-makers.

[Learn more](#)

onsemi



onsemi

80V T10 MOSFET NTTFSSH4D0N08XL

T10 LV-MV Si MOSFET Get Latest Version onsemi’s new T10 PowerTrench MOSFET technology (80V, 40V, 25V) delivers industry leading RDS(on), higher power density and reduced switching losses. [Learn more](#)

Solutions



3kW ACDC Analog PSU Solution

The 3kW ACDC Analog Power Supply Unit (PSU) uses the industry’s first mixed signal controller NCP1681 for Totem Pole PFC, delivering exceptional performance with a compact footprint. [Learn more](#)

AI Super computing Platforms / Liquid cooling for GenAI

Avnet together with the leading suppliers bring you the best Sensing technology / on the edge products.



Aeon
AI supercomputing solutions



Abracon
Abracon multi-phase assembly inductors



Amphenol
Leakage detection sensor cable assembly



Belfuse
TET4800-48-069RA



Molex
High-Current PowerPlane Busbar connectors



MPS
16V, 130A, Dual-Phase intelli-module



Murata
Power supply module D1U74T-W-3200-54-HBxC



Nordic
Nordic Edge AI Lab



Novosense
NSI3600D



Panasonic
HE-A relays for AI data centers products



Rohm
Power MOSFETs optimized for AI servers and data centers



Samtec
NovaRay® I/O 128 Gbps PAM4 panel mount cable system




STMicroelectronics
STM32N6



TE Connectivity
ICCON socket insert - High power current



Toshiba
N-channel power MOSFET

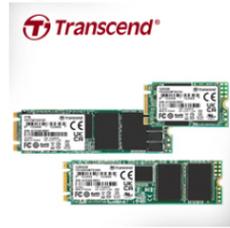

Transcend
MTS970P PLP SSD solutions



Vishay
PowerPAK® SO-8DC package

[Buy Now](#) | [Solutions](#) | [Line Card](#) | [Technical Articles](#) | [Contact Us](#)