


Light is freedom
The new OSOLON[®] Square

Light is OSRAM

OSRAM
Opto Semiconductors

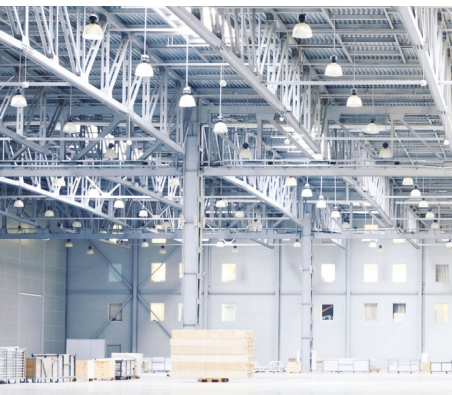

Advantages

OSLON® Square – the most compact high power LED with well known superior robustness, high reliability, long lifetime and very low thermal resistance. The OSLON® square family is designed for professional outdoor and indoor lighting, based on different color rendering. The key parameters are binned at high temperature which is closer to the real application conditions of our customers.

Features

- Ultra compact footprint (3 mm × 3 mm) for high-density arrays to simplify circuit designs
- Available with CRI 70, 80, 90
- Wide range of CCT selection
- Binned at 85 °C
- Very low thermal resistance
- Superior robustness and long lifetime
- Extendable range of current driving condition

For technical data please visit our website:

www.osram-os.com/products

Applications

- Streetlighting
- Tunnelling
- Pathlighting
- Architectural lighting
- Low bay, high bay
- Professional shop lights
- Museum lighting
- Spot lights



OSLON® Square on the Internet:
www.osram-os.com/oslon-square

More information about LED in General Lighting:

LED Light Site: ledlight.osram-os.com

LED Light for you Network: www.ledlightforyou.com

OSLON® Square

Type	CCT	CRI	Typ. Luminous flux @ 700 mA, 85 °C	Typ. Luminous efficacy @ 700 mA, 85 °C	Typ. Forward voltage @ 700 mA, 85 °C
GW CSSRM1.BM	2700 K – 4000 K	Typ. 95 (R9 typ 90)	172 lm @ 3000 K	88 lm/W @ 3000 K	2.8 V
GW CSSRM1.CC	2700 K – 4000 K 5700 K – 6500 K	Min. 90	196 lm @ 3000 K	100 lm/W @ 3000 K	2.8 V
GW CSSRM1.EC	2400 K – 5000 K	Min. 80	233 lm @ 3000 K	119 lm/W @ 3000 K	2.8 V
GW CSSRM1.PC	3000 K – 6500 K	Min. 70	281 lm @ 5000 K	143 lm/W @ 5000 K	2.8 V
GW CSSRM2.PM	3000 K – 6500 K	Min. 70	290 lm @ 5000 K	148 lm/W @ 5000 K	2.8 V

Asia

OSRAM Opto Semiconductors Asia Ltd.
 16/F China Resources Building
 26 Harbour Road, Wan Chai
 Hong Kong SAR
 Phone: +852 3652 5522
 Fax: +852 2802 0880
 E-mail: prasia@osram-os.com

Europe

OSRAM Opto Semiconductors GmbH
 Leibnizstraße 4
 D-93055 Regensburg, Germany
 Phone: +49 941 850 1700
 Fax: +49 941 850 3302
 E-mail: support@osram-os.com

USA

OSRAM Opto Semiconductors Inc.
 1150 Kifer Road, Suite 100
 Sunnyvale, CA 94086, USA
 Main Phone number: (408) 962-3700
 Main Fax: (408) 738-9120
 Inbound Toll Free: (866) 993-5211
 E-mail: info@osram-os.com